

 

# Proximity Sensor

## SMT-8-PS-K-LED-24-B

Part number: 175436

FESTO

Electric, contactless, PNP, for drives with T-slot, with cable.

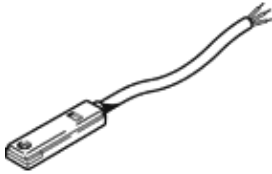

## Data sheet

Feature	Value
Design	for T-slot
Authorization	C-Tick
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Materials note	Free of copper and PTFE Conforms to RoHS
Measuring principle	Magneto-resistive
Ambient temperature	-20 ... 60 °C
Switch output	PNP
Switching element function	Normally open contact
Reproducibility of switching value	+/- 0,1 mm
Switch-on time	≤ 0.2 ms
Switch-off time	≤ 0.5 ms
Max. output current	100 mA
Max. contact rating DC	3 W
Voltage drop	≤ 1.8 V
Residual current	≤ 0.1 mA
Short circuit strength	Pulsing
Overload withstand capability	Available
Operating voltage range DC	10 ... 30 V
Polarity protected	for all electrical connections
Electrical connection	Cable 3-core
Connector exit direction	axial
Cable length	2.5 m
Cable attribute	Standard
Materials information, cable sheaths	PUR
Mounting type	Clamped in T-slot Insertable into slot lengthwise
Max. tightening torque	0.2 Nm
Product weight	30 g
Materials information, housing	TPE-U(PU) High alloy steel, non-corrosive
Operating status display	Yellow LED
Ambient temperature	-5 ... 60 °C
Protection class	IP65 IP67