


# Connecting cable KMP2-03-V-10-26

Part number: 175667

FESTO

For valve terminal VIMP/VIFB, max. 24 solenoid coils, 10 m long  
Type to be discontinued. Available until 2012.

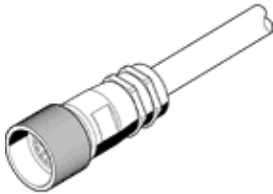

## Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	$\leq 250$ V
Operating voltage range DC	$\leq 300$ V
Permissible current load	7.5 A
Protection class	IP65
Ambient temperature	-5 ... 80 °C -20 ... 80 °C
Product weight	3,637 g
Electrical connection	Plug socket 26-pin
Cable structure	26 x 0,75 mm <sup>2</sup>
Cable diameter	15 mm
Cable length	10 m
Mounting type	With sleeve nut
Color code, core insulation	Black wires with consecutive white numbering from 1 to 26
Materials information for seals	CR Light and oil resistant
Materials information, housing	Copper alloy Nickel plated
Materials information, cable sheaths	PVC
Material information for crimp connectors	Copper alloy Gold plated