

# Valve kit CPV14-BS-5/3G-1/8


Part number: 176057

Classic - do not use for new projects

FESTO

in order to allow the function of a 5/3-way valve, closed in mid-position, to be created from two 3/2-way valves.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

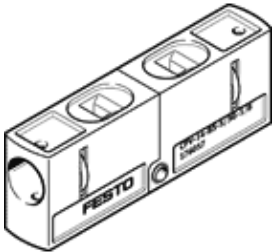

## Data sheet

Feature	Value
Valve function	5/3 closed
Working pressure	2.5 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	190 g
Mounting type	with through hole
Pneumatic connection, port 2	G1/8
Materials note	Conforms to RoHS
Material seals	NBR
Material housing	Zinc die-casting