


Multi-pin socket connector IMP1-SD-40

Part number: 18318

FESTO

Type to be discontinued. Available until 2011.

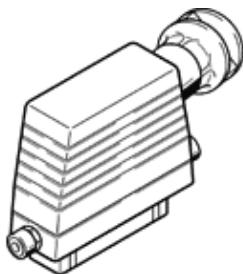

Data sheet

Feature	Value
Permissible cable diameter	18 ... 27 mm
Assembly position	Any
Operating voltage range AC	≤ 300 V
Operating voltage range DC	≤ 250 V
Permissible current load	10 A
Protection class	IP65
Ambient temperature	-40 ... 125 °C
Product weight	395 g
Terminal cross-section	1.5 mm ²
Electrical connection	Plug socket 40-pin
Cable gland connection	Pg29
Mounting type	With clamp strap
Materials information, housing	Plastic Die-cast light alloy
Material information for crimp connectors	Copper alloy Silver plated