


Multi-pin socket connector IMP1-SD-25-0,75

Part number: 18321

FESTO

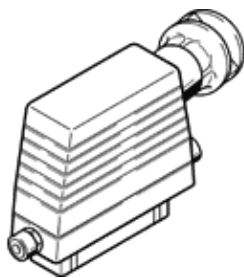

Data sheet

Feature	Value
Permissible cable diameter	7.5 ... 15 mm
Assembly position	Any
Operating voltage range AC	≤ 300 V
Operating voltage range DC	≤ 250 V
Permissible current load	10 A
Protection class	IP65
Ambient temperature	-40 ... 125 °C
Product weight	210 g
Terminal cross-section	0.75 mm ²
Electrical connection	Plug socket 25-pin
Cable gland connection	Pg16
Mounting type	With clamp strap
Materials information, housing	Plastic Die-cast light alloy
Material information for crimp connectors	Copper alloy Silver plated