


# Manual override HAB-1/8

Part number: 184585

FESTO

For exhaust air.

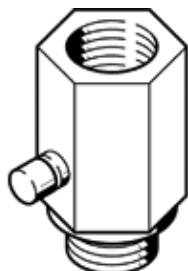

## Data sheet

Feature	Value
Nominal size	4.1 mm
Assembly position	Any
Valve function	exhaust component
Working pressure	0 ... 10 bar
Standard nominal flow rate, exhaust 0.6→0.5 MPa (6→5 bar, 87→72.5 psi)	165 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-20 ... 80 °C
Ambient temperature	-20 ... 80 °C
Max. tightening torque	8 Nm
Mounting type	Threaded
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Materials note	Conforms to RoHS
Material housing	Anodised wrought aluminium alloy