 



Clamping module EV-50-5

Part number: 184858

FESTO

With reset function

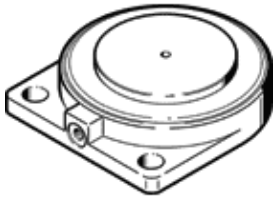

Data sheet

Feature	Value
Stroke	5 mm
Clamping surface	Ø 50
Assembly position	Any
Mode of operation	single-acting
Operating pressure MPa	≤ 0.6 MPa
Working pressure	≤ 6 bar
Operating pressure	≤ 87 psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B1/B2-L
RSBP classification to CD-0033	F5
Ambient temperature	-10 ... 40 °C
Product weight	68 g
Mounting type	with through hole
Pneumatic connection	M3
Material housing	Aluminum die cast
Material membrane	TPE-U(PU)