


# Protective conduit connector threaded connector MKGV-37-M40

Part number: 1877305

FESTO

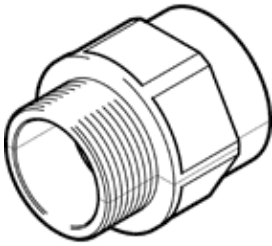

## Data sheet

Feature	Value
Assembly position	Any
Corrosion resistance classification CRC	2
Protection class	IP54
Ambient temperature	-40 ... 100 °C
Mounting type	with external (male) thread
Materials note	Conforms to RoHS
Materials information for fitting	PA