


# Pin adapter SIE-GA

Part number: 18780

FESTO

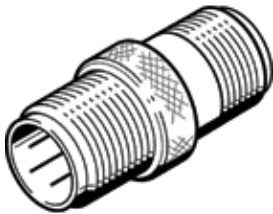

## Data sheet

Feature	Value
Assembly position	Any
Based on the standard	EN 61076-2-101 EN 61984
Operating voltage range AC	250 V
Operating voltage range DC	250 V
Surge strength	2.5 kV
Acceptable current load at 40°C	4 A
Degree of contamination	3
CE symbol (see declaration of conformity)	according to EU low voltage guideline
Protection class	IP67
Ambient temperature	-25 ... 85 °C
Max. tightening torque for locking	0.6 Nm
Product weight	23.5 g
Electrical connection	4-pin Design A M12x1 Plug straight
Mounting type	With sleeve nut
Materials information for locknut	Nickel-plated brass
Materials note	Conforms to RoHS
Material information for crimp connectors	Brass Nickel and gold plated