


Connector block VIGI-04-D-2-NPT

Part number: 18840

FESTO

For valve manifold

This product is only available if ordered from the Festo Corporation, USA.

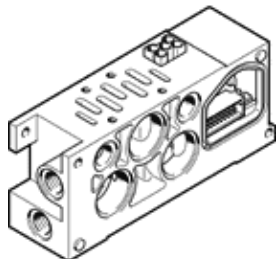

Data sheet

Feature	Value
Width	183 mm
Working pressure	-0.9 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Medium temperature	-10 ... 60 °C
Protection class	IP65
Ambient temperature	-10 ... 60 °C
Authorization	UL - Recognized (OL)
Mounting method for subbase	with through hole
Auxiliary pilot air port 12/14	NPT1/8-27
Pneumatic connection, port 1	NPT3/4-14
Pneumatic connection, port 2	NPT3/8-18
Pneumatic connection, port 3	NPT3/4-14
Pneumatic connection, port 4	NPT3/8-18
Pneumatic connection, port 5	NPT3/4-14
Materials information for subbase	Aluminum die cast