


Suction cup holder ESH-HA-4-QS

Part number: 189199

FESTO

without height compensator, vacuum connection at top, compensator secured by two hexagonal nuts.

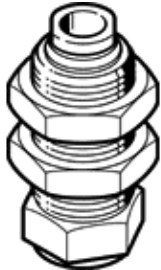

Data sheet

Feature	Value
Volume	0.719 cm ³
Assembly position	Vertical
Design structure	Vacuum connection at top
Correlation to suction-cup holder	Size 4
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	0 ... 60 °C
Product weight	30 g
Mounting type	with lock nut
suction cup mounting	M6
Vacuum connection	QS-6
Materials note	Conforms to RoHS
Material seals	NBR
Material bracket	Aluminum Nickel-plated brass POM Heat-treatment steel High alloy steel