


# Suction cup holder ESH-HE-2-M5

Part number: 189254

FESTO

without height compensator, for direct screw-in fitting.

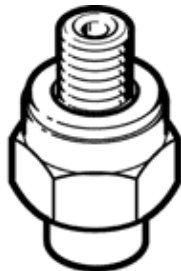

## Data sheet

Feature	Value
Nominal size	2 mm
Volume	0.036 cm <sup>3</sup>
Assembly position	Vertical
Design structure	Vacuum connection at top
Correlation to suction-cup holder	Size 2
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-10 ... 60 °C
Product weight	3 g
Mounting type	with external (male) thread Via vacuum port
suction cup mounting	Diameter 4 mm
Vacuum connection	M5
Materials note	Conforms to RoHS
Material seals	Wrought Aluminum alloy NBR POM Steel
Material bracket	Heat-treatment steel