


Addressing device ASI-PRG-ADR

Part number: 18959
Product to be discontinued

FESTO

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

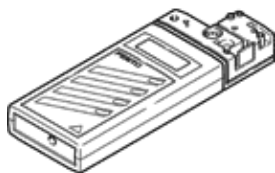

Data sheet

Feature	Value
Materials note	Conforms to RoHS
Number of function keys	5
Fieldbus interface, protocol	AS-Interface SPEC 3.0
Permissible load current	100 mA
Short circuit strength	Yes
Overload withstand capability	Available
Fieldbus interface, number of pins/wires	5
Fieldbus interface, type of connection	Plug socket
Fieldbus interface, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Display	LCD-Display
Control elements	5 keys Membrane keypad
Dimensions W x L x H	34 mm x 210 mm x 80 mm
Nominal operating voltage DC	28 V
Power supply	Lithium battery
CE symbol (see declaration of conformity)	according to EU-EMV guideline
PWIS conformity	VDMA24364-B2-L
Protection class	IP20
Ambient temperature	0 ... 40 °C
Product weight	610 g
Material housing	PA-reinforced