

Push-in/threaded L-fitting QSLF-1/8-5/16-U


Part number: 190729

FESTO

360° swivelling, internal thread with external hexagon.

This product is only available if ordered from the Festo Corporation, USA.

Type to be discontinued. Available until 2011.

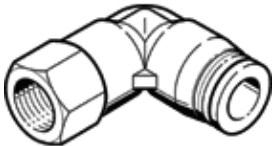

Data sheet

| Feature | Value |
|---|---|
| Size | Standard |
| Nominal size | 3.6 mm |
| Assembly position | Any |
| Container size | 1 |
| Design structure | Push/pull principle |
| Working pressure | -0.95 ... 10 bar |
| Temperature dependent working pressure | -0.95 ... 10 bar |
| Operating medium | Filtered compressed air Vacuum |
| Corrosion resistance classification CRC | 1 |
| Ambient temperature | -10 ... 60 °C |
| Authorization | Germanischer Lloyd |
| Max. tightening torque | 8 Nm |
| Product weight | 19 g |
| Pneumatic connection | NPT1/8-27 for tubing, 5/16" outside diameter |
| color of release ring | Grey |
| Materials note | Conforms to RoHS |
| Materials information, housing | PBT |
| Release ring material data | POM |
| Materials information for tubing seal | NBR |
| Hose clamping segment material data | High alloy steel, non-corrosive |