 



Non-return valve HA-1/8-QS-5/16-U

Part number: 190851

FESTO

Flow rate from the male thread to the QS plug connector.
This type is suitable for vacuum.

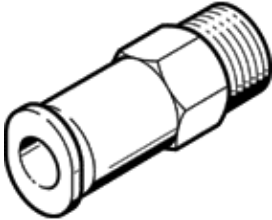

Data sheet

| Feature | Value |
|-------------------------------------|---|
| Valve function | Non-return function |
| Pneumatic connection, port 1 | 1/8 NPT |
| Pneumatic connection, port 2 | QS-5/16 |
| Mounting type | Threaded |
| Standard nominal flow rate | 331 l/min |
| Working pressure | -1 ... 10 bar |
| Ambient temperature | 0 ... 60 °C |
| Material housing | Brass |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:::] |
| Min. differential pressure, opening | 0.1 bar |
| Min. differential pressure, closing | 0.2 bar |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Product weight | 22 g |
| Materials note | Conforms to RoHS |