

 

Pressure regulator LRMA-QS-1/4-U

Part number: 190916
Product to be discontinued

FESTO

[With pressure gauge.](#)

[Type to be discontinued. Available until 2021. See Support Portal for alternative products.](#)

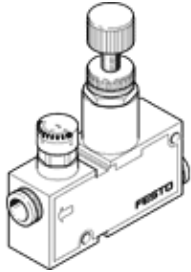

Data sheet

| Feature | Value |
|------------------------------|---|
| Controller function | Output pressure constant |
| Pneumatic connection, port 1 | QS-1/4 |
| Pneumatic connection, port 2 | QS-1/4 |
| Mounting type | with through hole |
| Inlet pressure 1 | 0 ... 10 bar |
| Ambient temperature | 0 ... 60 °C |
| Material housing | PBT-reinforced |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:::] |
| Assembly position | Any |
| Product weight | 57 g |
| Material of threaded plug | Brass |