


# Pressure regulator LR-10-32-UNF-QS-5/32-U

Part number: 190924  
Product to be discontinued

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

FESTO

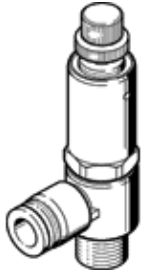

## Data sheet

Feature	Value
Controller function	Output pressure constant
Pneumatic connection, port 1	10-32 UNF-2A
Pneumatic connection, port 2	QS-5/32
Mounting type	Threaded
Inlet pressure 1	0 ... 10 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Assembly position	Any
Product weight	16 g
Material of threaded plug	Brass