


# Pressure regulator LR-1/4-NPT-QS-5/16-U

Part number: 190933  
Product to be discontinued

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

FESTO

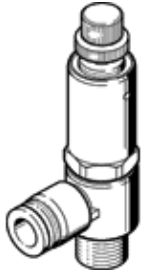

## Data sheet

Feature	Value
Controller function	Output pressure constant
Pneumatic connection, port 1	1/4 NPT
Pneumatic connection, port 2	QS-5/16
Mounting type	Threaded
Inlet pressure 1	0 ... 10 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Assembly position	Any
Product weight	60 g
Material of threaded plug	Brass