

# Non-return valve HBM-1/16-QS-3/16-U

Part number: 190948


FESTO

Flow rate from the QS plug connector to the male thread.

This product is only available if ordered from the Festo Corporation, USA.

This type is suitable for vacuum.

Type to be discontinued. Available until 2011.

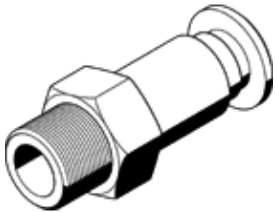

## Data sheet

| Feature                        | Value  |
|--------------------------------|--|
| Valve function                 | Non-return function  |
| Pneumatic connection, port 1   | QS-3/16  |
| Pneumatic connection, port 2   | NPT1/16-27   |
| Mounting type                  | Threaded   |
| Working pressure               | -1 ... 10 bar  |
| Ambient temperature            | 0 ... 60 °C  |
| Materials information, housing | Brass  |
| Operating medium               | Compressed air, filtered, unlubricated<br>Filtered, lubricated air |
| Product weight                 | 15 g   |