


# Plug SEA-5GS-11-DUO

Part number: 192010

FESTO

For valve manifolds.

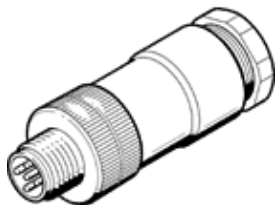

## Data sheet

Feature	Value
Based on the standard	EN 61076-2-101 EN 61984
Mounting type	with threaded sleeve
Assembly position	Any
Product weight	24 g
Electrical connection	5-pin Plug pattern type A to EN 175301-803 M12x1 Straight plug / screw terminal
Operating voltage range DC	≤ 60 V
Operating voltage range AC	≤ 60 V
Acceptable current load at 40°C	4 A
Surge strength	1.5 kV
Cable gland connection	Pg11
Permissible cable diameter	2 x 2.5 - 2.9 mm or 2 x 5 mm
Terminal cross-section	0.14 ... 0.5 mm <sup>2</sup>
Protection class	IP65
Ambient temperature	-40 ... 85 °C
CE symbol (see declaration of conformity)	according to EU low voltage guideline
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material housing	PA
Housing color	Black
Material of union nut	PA
Material electrical contact	Brass White bronze coated