


# Socket connector MSSD-EB-S-M14

Part number: 192745

FESTO

with insulation-piercing contacts

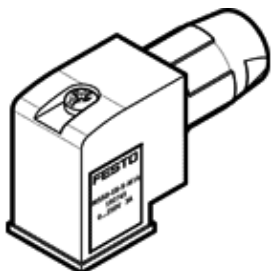

## Data sheet

Feature	Value
Connection frequency	10
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	17 g
Electrical connection	4-pin Plug socket Plug pattern type C to EN 175301-803
Cable diameter	4 ... 6 mm
Nominal conductor cross-section	0.25 ... 0.5 mm <sup>2</sup>
Protection class	IP67 to IEC 60529
Ambient temperature	-25 ... 90 °C
PWIS conformity	VDMA24364-B2-L
Material housing	PA
Housing color	Black