


# Passive guide axis FDG-18- -

Part number: 192850  
Product to be discontinued

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

FESTO

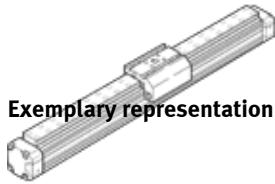

Exemplary representation

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Size	18
Stroke	1 ... 1,800 mm
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide axis without actuator
Max. speed	3 m/s
Corrosion resistance classification CRC	0 - No corrosion stress
Ambient temperature	-10 ... 60 °C
Materials note	Free of copper and PTFE
Material of guide component	Steel
Material housing	Wrought Aluminum alloy Anodized