


Limit stop element YSRWJ-5-8-A

Part number: 192968
Product to be discontinued

FESTO

[for linear module HMPL.](#)

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

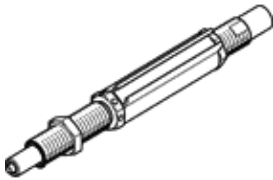

Data sheet

Feature	Value
Size	5
Stroke	8 mm
Cushioning	self-adjusting Soft characteristic
Assembly position	Any
Precision adjustment	0.03 mm
Position detection	For proximity sensor
Max. impact speed	2 m/s
Reset time short	≤ 0.2 s
Reset time long	< 1 s
Mode of operation	single-acting pushing action
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	0 ... 60 °C
Cushioning length	8 mm
Max. stop force	200 N
Max. energy consumption per stroke	1 J
Max. energy consumption per hour	10,000 J
Max. residual energy	0.01 J
Reset force	1 N
Product weight	45 g
Mounting type	with lock nut
Material seals	NBR
Material housing	Brass Nickel plated
Material piston rod	High alloy steel