


# Connecting cable KMYZ-2-24-10-LED

Part number: 193443

FESTO

for vacuum generators VAD-MYB, VADM, VADMI.

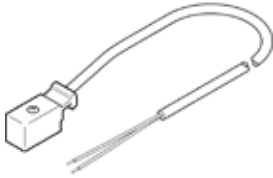

## Data sheet

Feature	Value
Switching position indicator	LED
Mounting type	On solenoid valve with self-tapping screw
Assembly position	Any
Product weight	170 g
Electrical connection	2-pin / 2-wire Angled socket / cable Square design/open end
Nominal operating voltage DC	24 V
Acceptable current load at 40°C	1 A
Protective earth connection	Not available
Cable length	10 m
Cable attribute	Standard
Cable diameter	3.4 mm
Cable structure	2x0,25
Protection class	IP65
Ambient temperature	-10 ... 50 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Material housing	PA
Material electrical contact	Bronze