


Plug socket with cable KMYZ-4-24-2,5-B

Part number: 193691

FESTO

For high speed valves

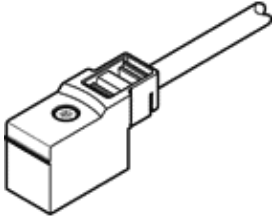

Data sheet

| Feature | Value |
|--|---|
| Mounting type | On solenoid valve with M2 central screw |
| Assembly position | Any |
| Product weight | 32 g |
| Electrical connection | Plug socket angled Cable Rectangular design, MSZC |
| Operating voltage range DC | 3 ... 36 V |
| Nominal operating voltage DC | 24 V |
| Acceptable current load at 40°C | 1 A |
| Protective earth connection | Not available |
| Cable length | 2.5 m |
| Cable attribute | Standard |
| Cable structure | 2x0,35 |
| Protection class | IP40 |
| Ambient temperature | -10 ... 50 °C |
| CE symbol (see declaration of conformity) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| Materials note | Conforms to RoHS |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| Material cable sheath | PVC |
| Material housing | PA |
| Material electrical contact | Bronze |