 



# Bellows cylinder EB-385-230

Part number: 193791

FESTO

Maintenance-free, no stick/slip effect.

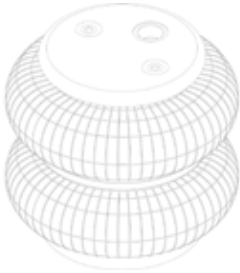

## Data sheet

Feature	Value
Size	385
Required installation diameter	400 mm
Stroke	230 mm
Max height when extended	310 mm
Max. tipping angle	20 deg
Max. offset	20 mm
Min. installation height	77 mm
Mode of operation	single-acting
Working pressure	0 ... 8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [-:~:4]
Note on operating and pilot medium	Lubricated operation not possible
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 70 °C
Reset force	400 N
Product weight	6,900 g
Mounting type	with internal (female) thread
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material bellows	NR/BR
Material housing	Steel Galvanized