


CAN interface SPC200-COM-CAN

Part number: 194017

FESTO

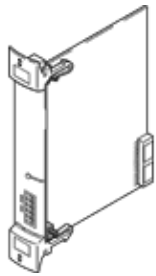

Data sheet

Feature	Value
Configuration support	EDS file
Typical current consumption, plug-in module	50 mA
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Product weight	80 g
Maximum address volume for outputs	8 byte
Maximum address volume for inputs	8 byte
Fieldbus interface address range	0 ... 63
Fieldbus interface design	Electrical isolation Layer 1 per ISO/DIS 11898 Standard high-speed to 1 Mbit Layer 2 per CAN specification V2.0 Device Net Release 2.0 Product code: 9434 Device Type: Comm. Adap. (12d) 125, 250, 500 kBaud
Electrical connection, fieldbus interface	Terminal strip 5-pin Per CIA DR-303-1
Installation space	From 3 up