 



Service unit FRCS-3/4-D-O-DI-MAXI

Part number: 194979

FESTO

Filter/regulator/lubricator combination, S series, with lockable regulator head.

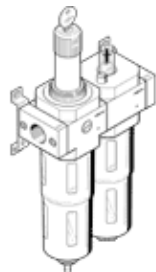

Data sheet

| Feature | Value |
|--------------------------------|--|
| Size | Maxi |
| Series | D |
| Actuator lock | Rotary knob with integrated lock |
| Assembly position | Vertical +/- 5° |
| Grade of filtration | 40 µm |
| Condensate drain | manual rotary |
| Design structure | Filter regulator without pressure gauge proportional standard mist lubricator |
| Max. condensate volume | 43 cm ³ |
| Bowl guard | Metal bowl guard |
| Pressure gauge | G1/4" prepared |
| Pressure control range | 0.5 ... 12 bar |
| Inlet pressure 1 | 1 ... 16 bar |
| Max. pressure hysteresis | 0.4 bar |
| Standard nominal flow rate | 3,800 l/min |
| Operating medium | Compressed air |
| Medium temperature | -10 ... 60 °C |
| Ambient temperature | -10 ... 60 °C |
| Product weight | 2,600 g |
| Mounting type | Line installation |
| Pneumatic connection, port 1 | G3/4 |
| Pneumatic connection, port 2 | G3/4 |
| Materials information, housing | Zinc die-casting |
| Materials information for bowl | PC |