 



Service unit FRCS-3/4-D-7-O-DI-MAXI-A

Part number: 195001

FESTO

Filter/regulator/lubricator combination, S series, with lockable regulator head.

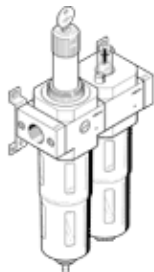

Data sheet

Feature	Value
Size	Maxi
Series	D
Actuator lock	Rotary knob with integrated lock
Assembly position	Vertical +/- 5°
Grade of filtration	40 µm
Condensate drain	fully automatic
Design structure	Filter regulator without pressure gauge proportional standard mist lubricator
Max. condensate volume	43 cm ³
Bowl guard	Metal bowl guard
Pressure gauge	G1/4" prepared
Pressure control range	0.5 ... 7 bar
Inlet pressure 1	1.5 ... 12 bar
Max. pressure hysteresis	0.4 bar
Standard nominal flow rate	5,000 l/min
Operating medium	Compressed air
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	2,600 g
Mounting type	Line installation
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G3/4
Materials information, housing	Zinc die-casting
Materials information for bowl	PC