


Connecting cable KMYZ-9-24-M8-0,5-LED-B

Part number: 196064

FESTO

For CPE-M1BH and CPE10SC solenoid valves, and MPV multi-pin distributor.

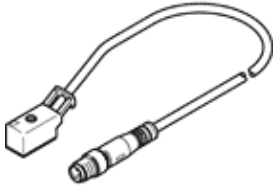

Data sheet

Feature	Value
Assembly position	Any
Additional functions	Reduction of holding current
Switching position indicator	LED
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Protection class	IP65
Ambient temperature	-10 ... 50 °C
Tightening torque	0.25 Nm
Product weight	18 g
Electrical connection	angled socket / straight plug square design / M8x1 2-pin / 3-pin
Cable structure	2x0,25
Cable diameter	3.4 mm
Cable length	0.5 m
Protective earth connection	Not available
Mounting type	On solenoid valve with M2 central screw
Materials note	Conforms to RoHS
Materials information, housing	PA
Materials information, cable sheaths	TPE-U(PUR)
Material information for crimp connectors	Bronze