


# Basic block CDVI5.0-GB4-MP

Part number: 196714

FESTO

For valve manifold CDVI, 4 valve positions.

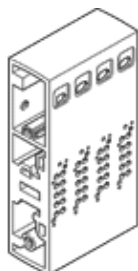

## Data sheet

Feature	Value
Length	112 mm
Max. number of valve positions	4
Corrosion resistance classification CRC	3
Authorization	C-Tick
Product weight	1,050 g
Mounting type	With internal thread and stud bolt
Scavenging orifice connection	G1/8
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 4	G1/8
Materials note	Conforms to RoHS