


# Connector block MHP1-PR2-3

Part number: 197191

FESTO

For semi in-line valve MHP1-...-HC/TC

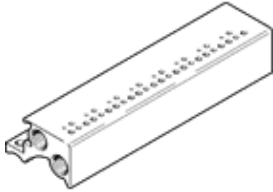

## Data sheet

| Feature                                 | Value   |
|---|---|
| Max. number of valve positions          | 2   |
| Working pressure                        | 0 ... 8 bar   |
| Operating medium                        | Compressed air in accordance with ISO8573-1:2010 [7:4:4]                    |
| Note on operating and pilot medium      | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 1 - Low corrosion stress  |
| PWIS conformity                         | VDMA24364-B2-L  |
| Ambient temperature                     | -10 ... 60 °C   |
| Mounting method for subbase             | with through hole   |
| Mounting method for valve               | with internal (female) thread   |
| Pneumatic connection, port 1            | M7  |
| Pneumatic connection, port 3            | M7  |
| Material of connecting plate            | Wrought Aluminum alloy  |