


Manifold block MHA1-P6-2-M3-PI

Part number: 197229

FESTO

with base plugs, for manifold block valves MHA1-...-PI

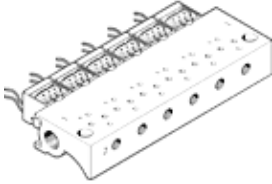

Data sheet

| Feature | Value |
|---|---|
| Max. number of valve positions | 6 |
| Working pressure | 0 ... 8 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:4:4] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B2-L |
| Ambient temperature | -10 ... 60 °C |
| Mounting method for subbase | with through hole |
| Mounting method for valve | with internal (female) thread |
| Pneumatic connection, port 1 | M7 |
| Pneumatic connection, port 2 | M3 |
| Material of connecting plate | Wrought Aluminum alloy |