

Valve manifold MH2

Part number: 197335


FESTO

With fast-switching valves.

Discontinued, available through 2007

To configure first add product to the shopping basket.

Depending on configuration, the technical data given on the data sheet and the relevant accessories might not match exactly for this product.

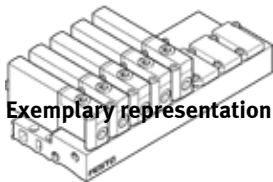

Exemplary representation

Data sheet

~ConfIndependentDatasheet

Feature	Value
Valve function	3/2 geschlossen monostabil 3/2 offen monostabil
Standard nominal flow rate	100 l/min
Pneumatic working line	M5
Operating pressure	-0.9 ... 8 bar
Electrical connection	Individual connection Multipol
Max. number of valve positions	10
Ambient temperature	-5 ... 40 °C
Width	10 mm
Protection class	IP40 IP65
Nominal size	2 mm
Grid dimension	14 mm
Exhaust-air function	throttleable
Type of actuation	electrical
Design structure	Pressure-relieved poppet valve
Type of piloting	direct
Valve manifold structure	Fixed-grid
Switching position indicator	Yes, with socket
Suitability for vacuum	Yes
Nominal operating voltage DC	5 V 24 V 12 V
Corrosion resistance classification CRC	2
Medium temperature	-5 ... 40 °C
Materials note	Free of copper and PTFE