


# Manifold block MHA2-PR8-3-M5

Part number: 197450

FESTO

for manifold block valves MHA2-...-HC/TC

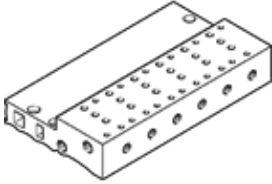

## Data sheet

| Feature                                 | Value                                  |
|---|--|
| Max. number of valve positions          | 8                                      |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress          |
| PWIS conformity                         | VDMA24364-B1/B2-L                      |
| Mounting method for subbase             | with through hole<br>with top-hat rail |
| Mounting method for valve               | with internal (female) thread          |
| Pneumatic ports 1/33                    | M7                                     |
| Pneumatic connection, port 2            | M5                                     |
| Pneumatic ports 3/11                    | M7                                     |
| Material of connecting plate            | Wrought Aluminum alloy                 |