


# Union nut MCK-PK-4-R

Part number: 205257

FESTO

Metal version.

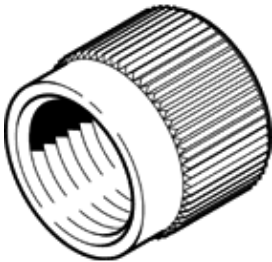

## Data sheet

Feature	Value
Size	Female thread M8x1
Operating pressure for entire temperature range	0 ... 1 MPa
Operating pressure complete temperature range	0 ... 10 bar
Operating pressure for entire temperature range	0 ... 145 psi
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 60 °C
Pneumatic connection, port 1	For tubing outside diameter 6 mm for barbed connector internal diameter 4 mm with nut
Material of union nut	Anodised wrought aluminium alloy
Materials note	Conforms to RoHS