


Rotary distributor

GF-1/4

Part number: 2094

FESTO

With one fixed air feed and four rotating outputs

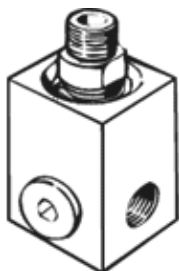

Data sheet

Feature	Value
Nominal size	11.5 mm
Assembly position	Any
Operating pressure complete temperature range	-0.95 ... 10 bar
Max. speed	300 1/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Pneumatic connection, port 1	Male thread G1/4
Pneumatic connection, port 2	Female thread 1/4
Materials note	Conforms to RoHS