


Axial kit EAMM-A-S38-60P

Part number: 2219110

☆ Core product range

Suitable for electric drives.

FESTO

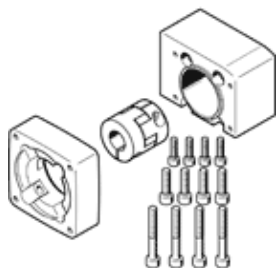

Data sheet

Feature	Value
Assembly position	Any
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	6.5 Nm
Product weight	530 g
Interface code, actuator	S38
Interface code, motor in	60P
Materials note	Conforms to RoHS