

# Silencer

 

## U-1/4

Part number: 2316

★ Core product range

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

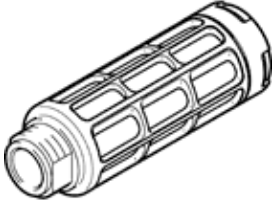

## Data sheet

Feature	Value
Assembly position	Any
Operating pressure MPa	0 ... 1 MPa
Working pressure	0 ... 10 bar
Flow rate to atmosphere	3,300 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
PWIS conformity	VDMA24364-B1/B2-L
Sound pressure level	76 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	7.7 g
Pneumatic connection	G1/4
Material of silencer insert	PE
Materials note	Conforms to RoHS