


# Gearbox

## EMGC-67-A-G1-SEC-67

Part number: 2321480  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2026. See Support Portal for alternative products.

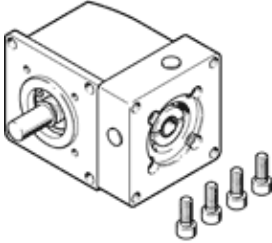

### Data sheet

Feature	Value
Gear unit flange size	67 mm
Motor flange size	67 mm
Torsional backlash	0.67 deg
Type of gear unit	Right-angle gear unit
Gear unit ratio	1:1
Max. input speed	4,500 1/min
Temperature range of gear unit	-20 ... 90 °C
PWIS conformity	VDMA24364 zone III
Protection class	IP54
Continuous output torque	2 Nm
Mass moment of inertia of gear unit	0.09 kgcm <sup>2</sup>
Max. output torque	2.1 Nm
Max. efficiency	90 %
Torsional resistance	0.105 Nm/arcmin
Product weight	930 g
Interface code, motor out	67A
Interface code, motor in	67A
Materials note	Conforms to RoHS