


# Braking resistance CACR-KL2-40-W2000

Part number: 2882343

FESTO

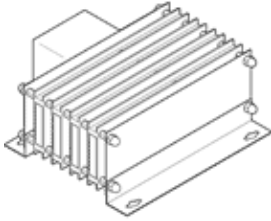

## Data sheet

Feature	Value
Size	500
Assembly position	Free convection Vertical
Pulse energy, braking resistor at 380 V	8,000 Ws
Pulse energy, braking resistor at 780 V	7,200 Ws
Performance at 35% duty cycle and 20°C	2,000 W
Rated capacity, braking resistance	800 W
Rated output, braking resistor at 380 V	600 W
Rated output, braking resistor at 780 V	480 W
Resistance value	40 Ohm
Authorization	c CSA us (OL) c UL us - Recognized (OL)
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Ambient temperature	0 ... 50 °C
Product weight	2,400 g
Mounting type	with through hole with accessories Optional
Materials note	Conforms to RoHS