


Clip fix tool AGTC-T-SG-1

Part number: 2927782

Product to be discontinued

FESTO

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

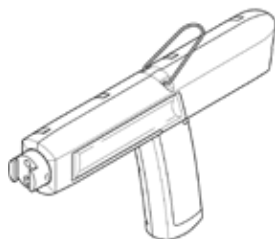

Data sheet

Feature	Value
Valve function	3/2 closed, monostable
Pneumatic connection, port 1	Female thread 1/4
Type of actuation	mechanical
Working pressure	2 ... 6 bar
Ambient temperature	5 ... 40 °C
Material housing	PA-reinforced TPE-S
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation not possible
CE symbol (see declaration of conformity)	according to EU machines guideline
Corrosion resistance classification CRC	1 - Low corrosion stress
Medium temperature	5 ... 40 °C
Max. tightening torque	15 Nm
Product weight	750 g
Material of connecting thread	Wrought aluminum alloy, anodized
Materials note	Conforms to RoHS
material retainer	Stainless spring steel
Material tool holder	High alloy steel
Tool holder	T-slot with thrust piece