


# Distributor block

## FR-4-1/4

Part number: 2960

FESTO

For distribution of compressed air.

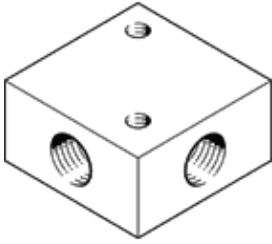

## Data sheet

Feature	Value
Nominal size	11.5 mm
Assembly position	Any
Operating pressure complete temperature range	0 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 80 °C
Product weight	68 g
Number of outputs	3
Number of supply lines	1
Pneumatic connection, port 1	Female thread 1/4
Pneumatic connection, port 2	Female thread 1/4
Materials note	Conforms to RoHS
Material housing	Aluminum Anodized