

 

Solenoid valve

JMZH-5/2-1,5-L-LED

Part number: 30221

FESTO

With solenoid coils and manual override, without sockets.

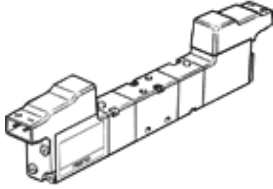

Data sheet

Feature	Value
Valve function	5/2 bistable
Standard nominal flow rate	80 l/min
Working pressure	2 ... 7 bar
Design structure	Piston slide
Protection class	IP40 with plug socket
Nominal size	1.5 mm
Type of piloting	Piloted
Switching time reversal	6 ms
Duty cycle	100%
Characteristic coil data	24V DC: 0,55W
Operating medium	Dried compressed air, lubricated or unlubricated
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
Product weight	55 g
Mounting type	with through hole
Pneumatic connection, port 1	Subbase Manifold module
Pneumatic connection, port 2	Subbase Manifold module
Pneumatic connection, port 3	Subbase Manifold module
Pneumatic connection, port 4	Manifold module
Pneumatic connection, port 5	Manifold module
Materials information for seals	NBR
Materials information, housing	Aluminum die cast