


# Connecting cable KMC-1-24DC-5-LED

Part number: 30933

FESTO

Pre-assembled, for C and N1 solenoids.

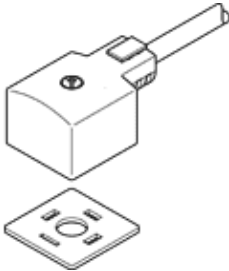

## Data sheet

Feature	Value
Operating status display	LED
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	320 g
Electrical connection	Plug socket Plug pattern type A to EN 175301-803
Nominal operating voltage DC	24 V
Polarity protected	for all electrical connections
Protective earth connection	Available
Cable length	5 m
Cable diameter	6 mm
Cable structure	3x0,75
Protection class	IP67 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PC
Material electrical contact	Bronze