


# Coupling EAMC-67-62-24-25

Part number: 3187895

FESTO

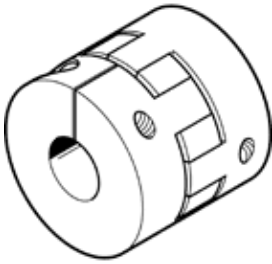

## Data sheet

| Feature                | Value                 |
|------------------------|-----------------------|
| Holder diameter 1      | 24 mm                 |
| Holder diameter 2      | 25 mm                 |
| Size                   | 67                    |
| Nominal length         | 62 mm                 |
| Assembly position      | Any                   |
| Max. speed             | 4,500 1/min           |
| PWIS conformity        | VDMA24364-B2-L        |
| Storage temperature    | -25 ... 60 °C         |
| Relative air humidity  | 0 - 95 %              |
| Ambient temperature    | -25 ... 60 °C         |
| Mass moment of inertia | 280 kgmm <sup>2</sup> |
| Transferable torque    | 143 Nm                |
| Product weight         | 435 g                 |
| Materials note         | Conforms to RoHS      |