


Swivel flange SNG-32

Part number: 32968
Product to be discontinued

FESTO

For DNG, DNGU cylinders. Matching clevis foot mounts LSNG, LSNSG.
Type to be discontinued. Available until 2014. See Support Portal for alternative products.

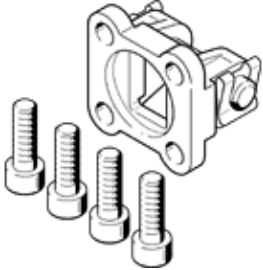

Data sheet

| Feature | Value |
|---|---|
| Size | 32 |
| Based on the standard | ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290) |
| Corrosion resistance classification CRC | 2 |
| Ambient temperature | -40 ... 150 °C |
| Product weight | 95 g |
| Materials note | Free of copper and PTFE Conforms to RoHS |
| Material information, mounting | Aluminum die cast |
| Material information, bolt | Steel Galvanized |
| Screw material data | Steel Galvanized |
| Material information for fuse | Spring steel, galvanized |