


# Guide unit FEN-50- -KF

Part number: 33486

FESTO

Discontinued, available through 2008

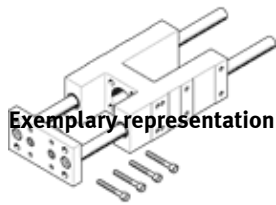

## Data sheet

| Feature                                   | Value                              |
|---|------------------------------------|
| Size                                      | 50                                 |
| Stroke                                    | 10 ... 500 mm                      |
| Assembly position                         | Any                                |
| Guide                                     | Recirculating ball bearing guide   |
| Design structure                          | Guide                              |
| Ambient temperature                       | -20 ... 80 °C                      |
| Displacement force                        | 15 N                               |
| Additional weight per 10 mm stroke        | 50 g                               |
| Basic weight for 0 mm stroke              | 4,030 g                            |
| Mounting type                             | with internal (female) thread      |
| Materials information for guide component | Heat-treatment steel               |
| Materials information, housing            | Wrought Aluminum alloy<br>Anodized |