


# Guide unit FEN-100- -KF

Part number: 33489

FESTO

Discontinued, available through 2008

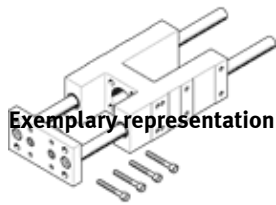

## Data sheet

Feature	Value
Size	100
Stroke	10 ... 500 mm
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide
Ambient temperature	-20 ... 80 °C
Displacement force	40 N
Additional weight per 10 mm stroke	80 g
Basic weight for 0 mm stroke	12,990 g
Mounting type	with internal (female) thread
Materials information for guide component	Heat-treatment steel
Materials information, housing	Wrought Aluminum alloy Anodized