


# Swivel flange SNGB-100

Part number: 34545  
Product to be discontinued

FESTO

For cylinders DNG, DNGU. Matching clevis foot mounts LN, LSN.  
Type to be discontinued. Available until 2014. See Support Portal for alternative products.

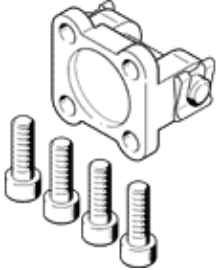

## Data sheet

| Feature                                 | Value   |
|---|---|
| Size                                    | 100   |
| Based on the standard                   | ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290) |
| Corrosion resistance classification CRC | 2   |
| Ambient temperature                     | -40 ... 90 °C   |
| Product weight                          | 1,040 g   |
| Materials note                          | Free of copper and PTFE<br>Conforms to RoHS                               |
| Material information, mounting          | Aluminum die cast   |
| Material information, bolt              | Steel<br>Galvanized   |
| Materials information for bearing       | Plastic   |
| Screw material data                     | Steel<br>Galvanized   |
| Material information for fuse           | Spring steel, galvanized  |